

GA Gaskets



- Broad application range
- Multiple industry standard profiles
- Clip-on or groove mount

Material and Finish



GASKET: EPDM Sponge, black
 CARRIER: 70 Durometer EPDM, black
 SUBSTRATE: Steel wire

Product Strength Guidelines



Flammability Rating: UL 94 - HB

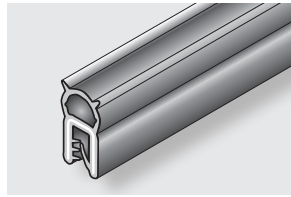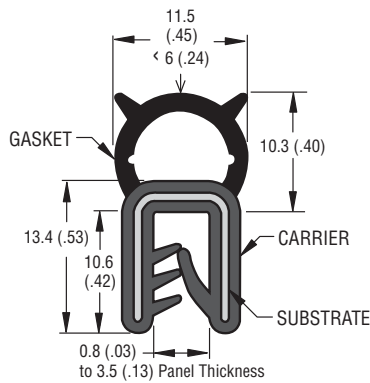



Gasket 007	
PART NUMBER	Length
GA-007-82-M500	50 m

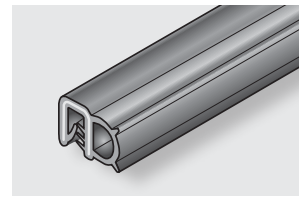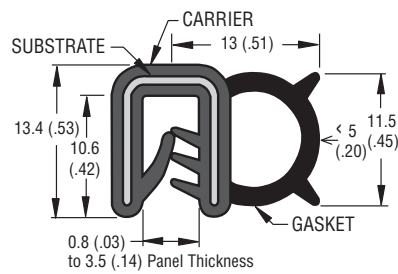



Gasket 202	
PART NUMBER	Length
GA-202-82-M500	50 m

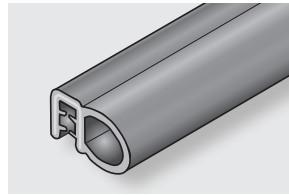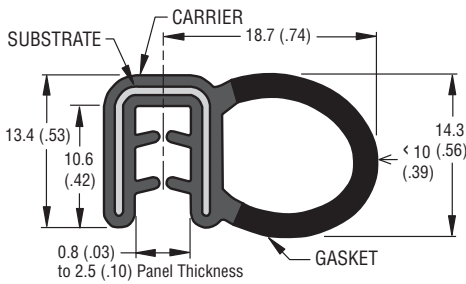



Gasket 204	
PART NUMBER	Length
GA-204-82-M500	50 m

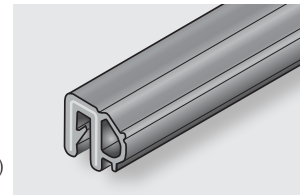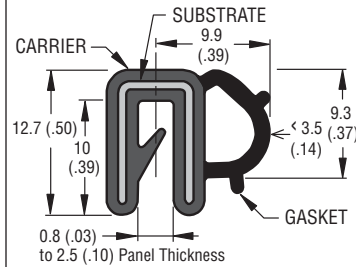

Gasket 206	
PART NUMBER	Length
GA-206-82-M500	50 m

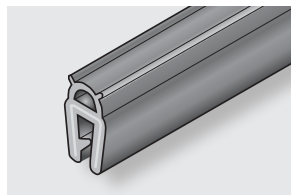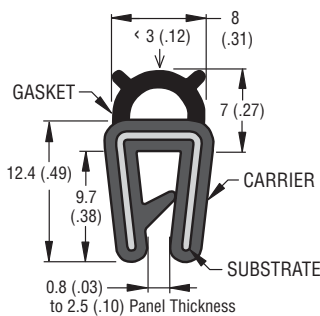

Gasket 209	
PART NUMBER	Length
GA-209-82-M500	50 m

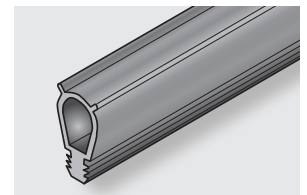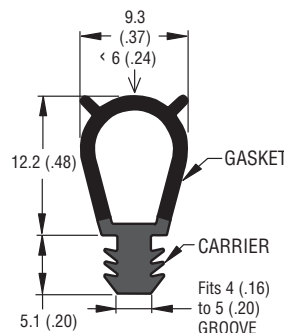

Gasket 704	
PART NUMBER	Length
GA-704-81-M500	50 m

For additional specifying and ordering information, downloadable CAD files, and 3-D solid models visit: www.southco.com or e-mail: info@southco.com