


# LIGHTING & ELECTRICAL

## BOW LIGHT

 
- 316 stainless steel
- Heavy-duty, highly polished investment cast construction
- Bicolor deck mount light
- Two miles visibility

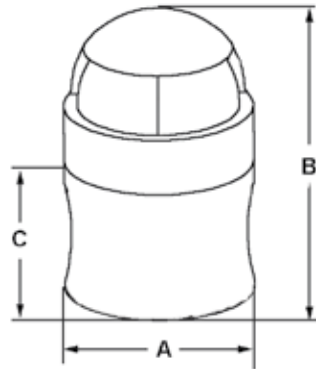

Part No	A mm	B mm	C mm
M7-80-9002405	68 (2 3/4")	54 (2 1/8")	-
M7-80-9102601	68 (2 3/4")	80 (3 1/8")	22 (7/8")
M7-80-9402801	76 (3")	100 (4")	41 (1 7/8")

## SWIVEL POLE LIGHT


- 316 stainless steel
- All-round light
- 2 NM visibility
- Can be swivelled up or down to desired position



Part No	A mm	B mm	C mm	D mm
M7-80-9402530	1060 (41 3/4")	64 (2 1/2")	70 (2 3/4")	25 (1")
M7-80-9402532	300 (11 13/16")	64 (2 1/2")	70 (2 3/4")	25 (1")

## REMOVABLE MASTHEAD LIGHT

- 316 stainless steel
- Rubber cover protects the socket when light is stowed away

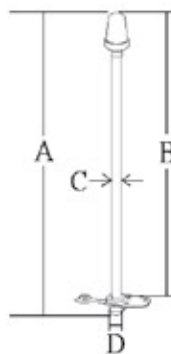


Part No	A mm	B mm	C mm	D mm
M7-80-9102331	625 (24 5/8")	548 (21 1/2")	19 (3/4")	23 (7/8")
M7-80-9402520	1110 (43 3/4")	1033 (40 5/8")	19 (3/4")	23 (7/8")
M7-80-9002308-L	Replacement lens for mast head light			
M7-80-9002308-B	Replacement bulbs for mast head light			

# LIGHTING & ELECTRICAL

## CABLE OUTLET


- 316 stainless steel
- Features bushings and gasket to fit a wide range of cable diameters

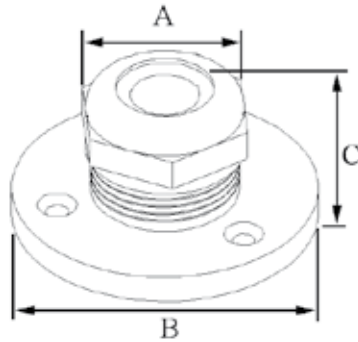

Part No	Cable Ø	A mm	B mm	C mm
M7-81-9303825	4-11 (3/16" - 7/16")	22 (7/8")	49 (1 7/8")	21 (7/8")
M7-81-9303827	12-20 (1/2" - 7/8")	32 (1 1/4")	62 (2 1/2")	28 (1 1/8")

## READING LIGHT

- 304 stainless steel
- Replaceable Halogen bulb
- Adjustable angles

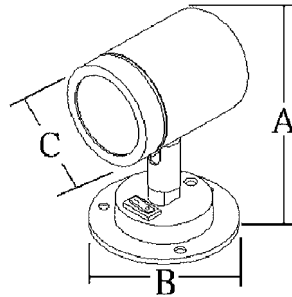

Part No	A	B	C
M7-80-9002303	120 (4 3/4")	85 (3 3/8")	50 (2")