


# MP Point Coat Hook


## Pop-up hook



### H Housing Style (with hanger image, I = 2)

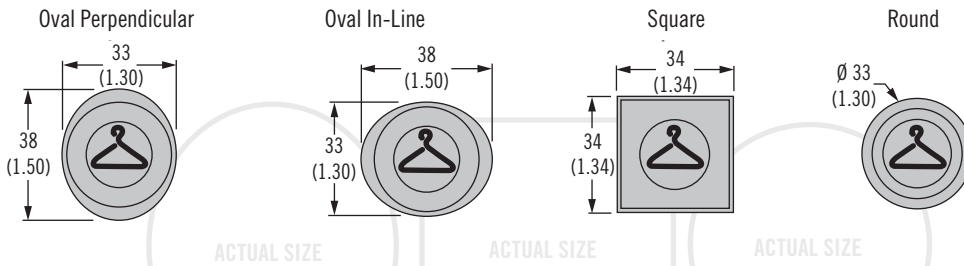

### H Housing Style (without hanger image, I = 3)

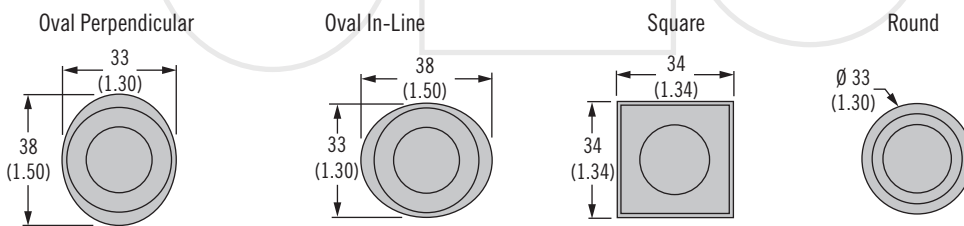

- Flush pop out hook
- Single, round hole installation
- Corrosion-resistant materials

### Material and Finish


Housing: Glass-filled nylon

Flange and hook: Zinc alloy, plated

### Installation Notes

Maximum tightening torque on mounting nut: 4.5 N·m (40 in·lbf)

### Installation

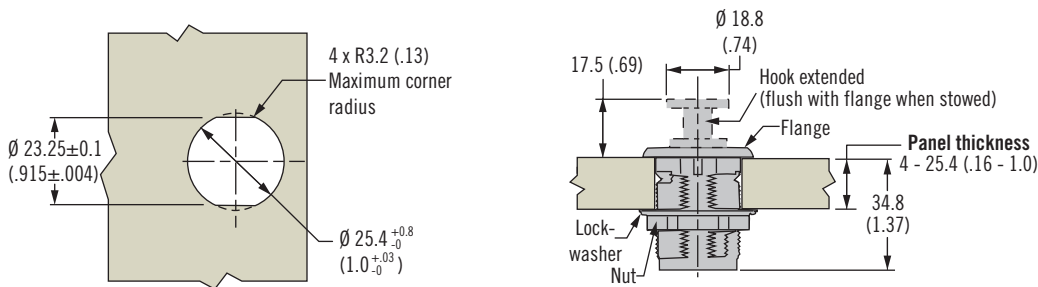

### Part Number Selection

**H** Housing style      **I** Image

11 Oval perpendicular      2 Hanger

12 Oval in-line      3 Blank

21 Square

31 Round

**F** Flange finish      **K** Hook finish

1 Chrome plated      1 Chrome plated

2 Satin chrome plated      2 Satin chrome plated

3 Brushed nickel plated      3 Brushed nickel plated

4 Diamond brass plated      4 Diamond brass plated

5 Black powder coated (**I** = 3 Blank)      5 Black powder coated (**I** = 3 Blank)

6 Satin nickel plated      6 Satin nickel plated

**MP - 07 - H I - F K**



Dimensions in millimeters (inch) unless otherwise stated

Other options available. For complete details on variety, part numbers, installation and specification, go to



[www.southco.com/MP2](http://www.southco.com/MP2)